


**B 53030**  
**U-NUT® self-locking nuts**

With metric fine thread of stainless steel

Steel 5 | zinc-plated | Cr(VI)-free | Metric standard thread

Further information: material nuts: steel SS400 | zinc-plated | material insert: stainless steel

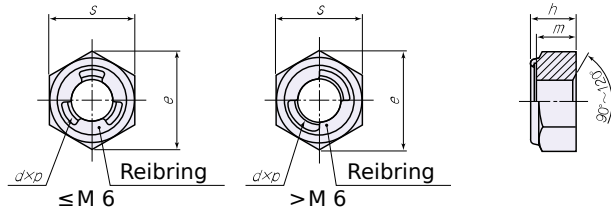

Diameter (d)	e nominal size	h		m nominal size	s		Pitch (P)	Sicherungsring
		nominal size	min.   max.		nominal size	min.   max.		
M4	8.1	3.8	3.5   4.1	3.0	7	6.80   7	0.70	dreifach je 60°
M5	9.2	4.6	4.3   4.9	3.9	8	7.80   8	0.80	dreifach je 60°
M6	11.5	5.1	4.8   5.4	4.2	10	9.80   10	1.00	dreifach je 60°
M8	15.0	7.3	6.9   7.7	6.1	13	12.75   13	1.25	zweifach je 90°
M10	19.6	8.3	7.9   8.7	7.1	17	16.75   17	1.50	zweifach je 90°
M12	21.9	10.5	10.1   10.9	9.0	19	18.65   19	1.75	zweifach je 90°
M14	25.4	12.5	12.0   13.0	11.0	22	21.65   22	2.00	zweifach je 90°
M16	27.7	14.5	14.0   15.0	13.0	24	23.65   24	2.00	zweifach je 90°
M20	34.6	17.5	17.0   18.0	15.4	30	29.65   30	2.50	zweifach je 90°
M24	41.6	21.5	20.9   22.1	18.8	36	35.60   36	3.00	zweifach je 90°
M30	53.1	27.0	26.2   27.8	24.0	46	45.60   46	3.50	zweifach je 90°

All technical data refer to the measure mm

