


DIN 127 A
Spring washers

Form A: bent open

Stainless steel A2 | Cr(VI)-free

Further information: Norm has been withdrawn without replacement

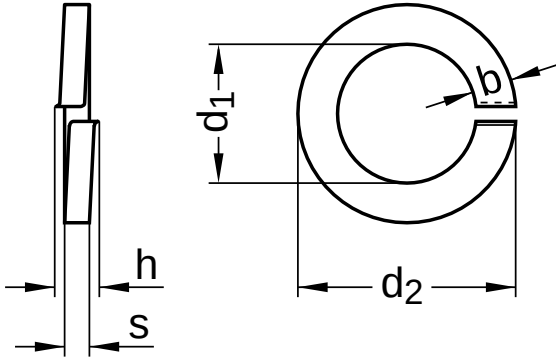

Diameter (d)	nominal size	b		d ₁		d ₂ max.	h		nominal size	s	
		min.	max.	min.	max.		min.	max.		min.	max.
3	1.3	1.20	1.40	3.1	3.4	6.2	1.9	2.1	0.8	0.70	0.90
4	1.5	1.40	1.60	4.1	4.4	7.6	2.1	2.5	0.9	0.80	1.00
5	1.8	1.70	1.90	5.1	5.4	9.2	2.7	3.2	1.2	1.10	1.30
6	2.5	2.35	2.65	6.1	6.5	11.8	3.6	4.2	1.6	1.50	1.70
8	3.0	2.85	3.15	8.1	8.5	14.8	4.6	5.4	2.0	1.90	2.10
10	3.5	3.30	3.70	10.2	10.7	18.1	5.0	5.9	2.2	2.05	2.35

All technical data refer to the measure mm

