


DIN 431

Pipe nuts

With pipe thread | form B

Brass | Cr(VI)-free | Pipe thread

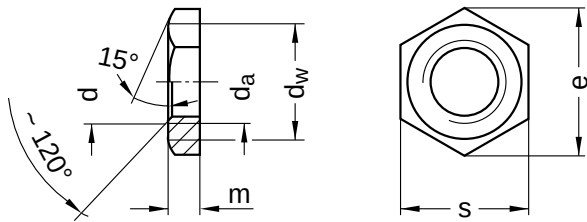

Diameter (d)	d _a max.	d _w min.	e min.	m		s		Tool size
				min.	max.	min.	max.	
G 1/8	10.5	16.5	19.85	6	6.48	17.57	18	SW 18
G 1/4	14.2	19.1	22.78	6	6.48	20.16	21	SW 21
G 3/8	18.0	24.8	29.56	7	7.58	26.16	27	SW 27
G 1/2	22.6	31.3	37.29	8	8.58	33.00	34	SW 34
G 3/4	28.6	32.3	39.55	9	9.58	35.00	36	SW 36
G 1	35.6	42.8	50.85	10	10.58	45.00	46	SW 46

All technical data refer to the measure mm

