


DIN 84 identical with ISO 1207

Cylinder screws

Slotted

Steel 4.8 | zinc-plated, thick-film passivated (VZD) | Cr(VI)-free | Metric thread

Further information: DIN standard has been withdrawn

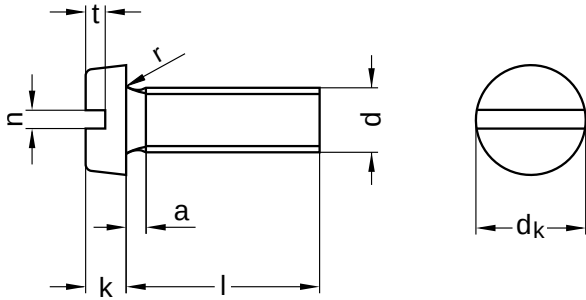

Diameter (d)	a max.	d _k		k		nominal size	n		r min.	Pitch (P)	t min.
		min.	max.	min.	max.		min.	max.			
M3	1.0	5.32	5.5	1.86	2.0	0.8	0.86	1.00	0.10	0.5	0.85
M4	1.4	6.78	7.0	2.46	2.6	1.2	1.26	1.51	0.20	0.7	1.10
M5	1.6	8.28	8.5	3.12	3.3	1.2	1.26	1.51	0.20	0.8	1.30
M6	2.0	9.78	10.0	3.60	3.9	1.6	1.66	1.91	0.25	1.0	1.60

nominal size	Length (l)	
	min.	max.
5	4.76	5.24
6	5.76	6.24
8	7.71	8.29
10	9.71	10.29
12	11.65	12.35
16	15.65	16.35

nominal size	Length (l)	
	min.	max.
18	17.65	18.35
22	21.58	22.42
25	24.58	25.42
45	44.50	45.50

Diameter (d)	Length (l)									
	5	6	8	10	12	16	18	22	25	45
M3	●	●	●	●	●	●	●	●	●	●
M4		●	●	●		●	●	●	●	
M5			●	●						
M6			●		●				●	

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

