

DIN 960 similar to ISO 8765


Hexagon head bolts

Hexagon head | with body

Steel 8.8 | bright | Cr(VI)-free | Metric fine thread

Further information: DIN-standard has been withdrawn | changed spanner widths for M10, M12, M14 and M22

There is a separation into product classes A and B, with the data sheet showing the largest range of values. For more information, see the technical details of the selected article.

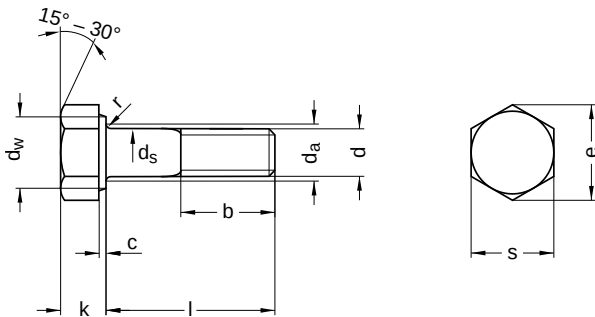

Diameter (d)	b			c		d _a	d _w	e
	l up to 125	l up to 200	l longer than 200	min.	max.	max.	min.	min.
M8 x 1	22	28	41	0.15	0.6	9.2	11.4	14.20
M10 x 1	28	32	45	0.15	0.6	11.2	15.4	18.72
M10 x 1.25	28	32	45	0.15	0.6	11.2	15.4	18.72
M12 x 1.25	30	38	49	0.15	0.6	13.7	17.2	20.88
M12 x 1.5	30	38	49	0.15	0.6	13.7	17.2	20.88
M14 x 1.5	34	40	53	0.15	0.6	15.7	20.1	23.91
M16 x 1.5	38	44	57	0.20	0.8	17.7	22.0	26.17
M18 x 1.5	42	48	61	0.20	0.8	20.2	24.8	29.56
M20 x 1.5	48	52	65	0.20	0.8	22.4	27.7	32.95
M20 x 2	48	52	65	0.20	0.8	22.4	27.7	32.95
M24 x 2	54	60	73	0.20	0.8	26.4	33.2	39.55

Diameter (d)	nominal size	k		r	s		Pitch (P)	Tool size
		min.	max.	min.	nominal size	min.		
M8 x 1	5.3	5.06	5.54	0.4	13	12.57	1.00	SW 13
M10 x 1	6.4	6.11	6.60	0.4	17	16.57	1.00	SW 17
M10 x 1.25	6.4	6.11	6.60	0.4	17	16.57	1.25	SW 17
M12 x 1.25	7.5	7.21	7.70	0.6	19	18.48	1.25	SW 19
M12 x 1.5	7.5	7.21	7.70	0.6	19	18.48	1.50	SW 19
M14 x 1.5	8.8	8.51	9.09	0.6	22	21.16	1.50	SW 22
M16 x 1.5	10.0	9.71	10.29	0.6	24	23.16	1.50	SW 24
M18 x 1.5	11.5	11.15	11.85	0.8	27	26.16	1.50	SW 27
M20 x 1.5	12.5	12.15	12.85	0.8	30	29.16	1.50	SW 30
M20 x 2	12.5	12.15	12.85	0.8	30	29.16	2.00	SW 30
M24 x 2	15.0	14.65	15.35	0.8	36	35.00	2.00	SW 36

All technical data refer to the measure mm



DIN 960 similar to ISO 8765

Hexagon head bolts

Hexagon head | with body

Steel 8.8 | bright | Cr(VI)-free | Metric fine thread

nominal size	Length (l)	
	min.	max.
35	34.50	35.50
40	39.50	40.50
45	44.50	45.50
50	49.50	50.50
55	54.40	55.60
60	59.40	60.60
65	64.40	65.60
70	69.40	70.60

nominal size	Length (l)	
	min.	max.
75	74.40	75.60
80	79.40	80.60
90	88.25	91.75
100	98.25	101.75
110	108.25	111.75
120	118.25	121.75
130	128.00	132.00
140	138.00	142.00

nominal size	Length (l)	
	min.	max.
150	148.00	152.00
160	158.00	162.00
170	168.00	172.00
200	197.70	202.30

Diameter (d)	Length (l)																			
	35	40	45	50	55	60	65	70	75	80	90	100	110	120	130	140	150	160	170	200
M8 x 1	●	●	●	●	●			●	●	●	●	●								
M10 x 1		●	●	●		●							●	●						
M10 x 1.25			●	●	●	●				●	●	●		●	●					
M12 x 1.25				●		●		●			●		●	●	●					
M12 x 1.5			●	●	●	●		●	●	●	●	●		●	●	●				
M14 x 1.5				●	●		●		●	●	●	●	●	●	●	●				
M16 x 1.5					●		●	●	●	●	●	●	●	●	●	●	●	●	●	●
M18 x 1.5						●		●		●	●	●								
M20 x 1.5							●		●		●	●	●		●	●	●	●		●
M20 x 2							●		●	●	●	●								
M24 x 2											●	●		●	●	●				

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

