


**DIN 980** similar to ISO 7042

## Hexagon nuts

With clamping part | all metal | form V: one-piece

Stainless steel A2 | Cr(VI)-free | Metric thread

Further information: DIN standard has been withdrawn | modified nut height and wrench width

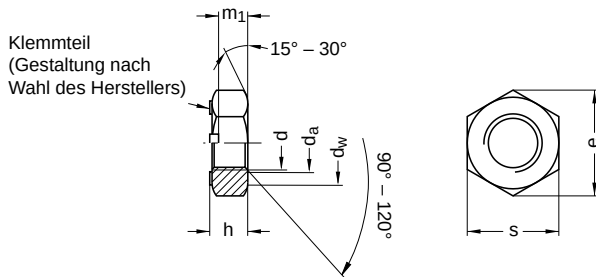

| Diameter<br>(d) | d <sub>a</sub> |       | d <sub>w</sub> | h    |      | m <sub>1</sub> | e     | s     |      | Pitch<br>(P) | Tool<br>size |
|-----------------|----------------|-------|----------------|------|------|----------------|-------|-------|------|--------------|--------------|
|                 | min.           | max.  |                | min. | max. |                |       | min.  | max. |              |              |
| M5              | 5              | 5.75  | 6.9            | 4.8  | 5.1  | 2.75           | 8.79  | 7.78  | 8    | 0.80         | SW 8         |
| M6              | 6              | 6.75  | 8.9            | 5.7  | 6.0  | 3.30           | 11.05 | 9.78  | 10   | 1.00         | SW 10        |
| M8              | 8              | 8.75  | 11.6           | 7.5  | 8.0  | 4.40           | 14.38 | 12.73 | 13   | 1.25         | SW 13        |
| M10             | 10             | 10.80 | 15.6           | 9.0  | 10.0 | 5.50           | 18.90 | 16.73 | 17   | 1.50         | SW 17        |
| M12             | 12             | 13.00 | 17.4           | 11.0 | 12.0 | 6.60           | 21.10 | 18.67 | 19   | 1.75         | SW 19        |

All technical data refer to the measure mm

