


EXPANSIONERT 2

Brass | Typ 0235 | flange

Advantages:

- For reactive resins, PUR, elastomers, integral hard foams as well as for wood composite materials
- Wear-resistant threads
- Quick, cost-effective installation

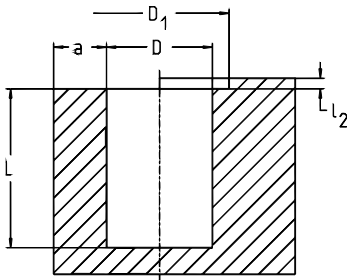

Diameter (d)	Article number	d ₃ nominal size	Length (l) nominal size	a min.	l ₂	l ₁	D1	Outer diameter (d2)	L min.
M 3	02351030008	7	8.0	4	0.8	3	7.2	5.9	8.2
M 4	02351040095	8	9.5	5	0.8	4	8.2	6.9	9.8
M 5	02351050011	10	11.0	6	0.8	5	10.2	8.4	11.3
M 6	02351060125	10	12.5	6	0.8	6	10.2	8.4	12.8

All technical data refer to the measure mm

