

E 1411


EJOT®-PT screws

Linsenkopf mit angepresster Scheibe | Kreuzschlitz Z (Pozidriv)

Steel 10 | zinc-plated | Cr(VI)-free | Self-tapping thread

Further information: For further information and CAD-files please follow the link to the EJOT-homepage:

<http://www.ejot.com/industry>

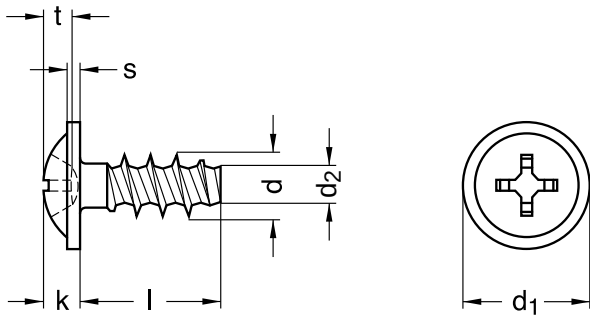

Diameter (d)	d ₁ nominal size	d ₂ nominal size	k nominal size	s		Pitch (P)	t	
				min.	max.		max.	min.
2.2	4.4	1.25	1.6	0.5	0.7	0.98	1.14	0.68
2.5	5	1.4	1.8	0.6	0.8	1.12	1.28	0.82
3	6	1.66	2.1	0.7	0.9	1.34	1.61	1.15
3.5	7	1.91	2.4	0.8	1.0	1.57	1.70	1.07
4	8	2.17	2.5	0.9	1.1	1.79	1.96	1.33
5	10	2.68	3.2	1.1	1.3	2.24	2.61	1.98
6	12	3.19	4.0	1.3	1.5	2.69	2.90	2.24

Length (l) nominal size
5
6
7
8
10
12

Length (l) nominal size
14
16
20
30

All technical data refer to the measure mm



E 1411

EJOT®-PT screws

Linsenkopf mit angepresster Scheibe | Kreuzschlitz Z (Pozidriv)

Steel 10 | zinc-plated | Cr(VI)-free | Self-tapping thread

Diameter (d)	Length (l)									
	5	6	7	8	10	12	14	16	20	30
2.2		●		●	●					
2.5	●	●	●	●	●	●				
3		●	●	●	●	●				
3.5			●	●		●				
4				●	●	●	●	●		
5					●		●			●
6										●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

