


# HITSERT® 3

Brass | Type 0935 | standard

**Advantages:**

- Well-proven 8° taper angle
- Self-centring
- Large contact surface for plastic prior to installation
- Flexible installation due to thermal installation, tapping or cold insertion
- Short installation times
- Milled external contour (low tolerances)
- Efficient seal inserts

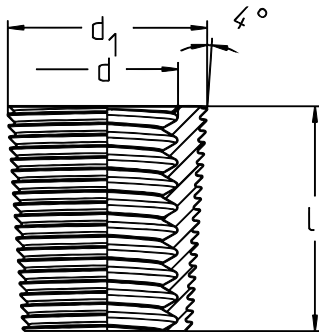

Diameter (d)	Article number	d <sub>1</sub> nominal size	Length (l) nominal size	a min.	L min.
M 3	09351030005	4.7	5.0	1.8	6.0
M 4	09351040075	6.1	7.5	2.0	8.5
M 5	09351050009	7.3	9.0	2.0	10.0
M 6	09351060010	8.9	10.0	2.5	11.0

All technical data refer to the measure mm

