


ISO 7089 similar to DIN 125

Washers

ISO 7089 | Washers | Steel 200 HV | zinc-plated | Cr(VI) - free

Steel 200 HV | zinc-plated | Cr(VI)-free

Further information: DIN standard has been withdrawn

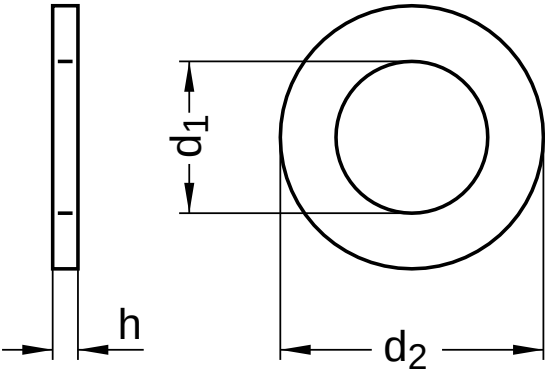

Diameter (d)	d ₁		d ₂		nominal size	h	
	min.	max.	min.	max.		min.	max.
3.2	3.2	3.38	6.64	7.00	0.5	0.45	0.55
3.7	3.7	3.88	7.64	8.00	0.5	0.45	0.55
4.3	4.3	4.48	8.64	9.00	0.8	0.70	0.90
5.3	5.3	5.48	9.64	10.00	1.0	0.90	1.10
6.4	6.4	6.62	11.57	12.00	2.5	2.30	2.70
8.4	8.4	8.62	15.57	16.00	1.6	1.40	1.80
10.5	10.5	10.77	19.48	20.00	2.0	1.80	2.20
13	13.0	13.27	23.48	24.00	2.5	2.30	2.70
15	15.0	15.27	27.48	28.00	2.5	2.30	2.70
17	17.0	17.27	29.48	30.00	3.0	2.70	3.30
19	19.0	19.33	33.38	34.00	3.0	2.70	3.30
21	21.0	21.33	36.38	37.00	3.0	2.70	3.30
25	25.0	25.33	43.38	44.00	4.0	3.70	4.30
28	28.0	28.33	49.38	50.00	4.0	3.70	4.30
31	31.0	31.39	56.00	56.26	4.0	3.70	4.30
34	34.0	34.62	58.80	60.00	5.0	4.40	5.60
37	37.0	37.62	64.80	66.00	5.0	5.60	4.40
42	42.0	42.62	70.80	72.00	6.0	5.40	6.60
45	45.0	45.62	76.80	78.00	8.0	7.00	9.00
56	56.0	56.74	96.60	98.00	8.0	7.00	9.00

All technical data refer to the measure mm

