

RIVQUICK® Coloured blind rivets

Dome head | Colored rivet brown RAL8017

Note: aluminium body and steel mandrel

Technical information can be found on the last page.



Diameter (d)	Article number	d ₁ nominal size	d ₂ nominal size	Drilling diameter d nominal size	e	
					min.	max.
3	22161130062	3	6.5	3.1 - 3.2	1.0	3.0
	22161130082				3.0	5.0
	22161130102				5.0	7.0
	22161130122				7.0	9.0
3.2	22161132062	3.2	6.5	3.3 - 3.4	1.0	3.0
	22161132082				3.0	5.0
	22161132102				5.0	7.0
	22161132122				7.0	9.0
4	22161140072	4	8	4.1 - 4.2	2.0	3.5
	22161140082				3.0	4.5
	22161140092				4.0	5.5
	22161140102				5.0	6.5
	22161140112				6.0	7.5
	22161140122				7.0	8.5
	22161140142				8.0	10.5
	22161140162				10.0	12.5
	22161140182				12.0	14.5
22161140202	14.0	16.5				
4.8	22161148072	4.8	9.5	4.9 - 5.0	1.5	3.0
	22161148082				2.5	4.0
	22161148092				3.5	5.0
	22161148102				4.5	6.0
	22161148112				5.5	7.0
	22161148122				6.5	8.0
	22161148142				7.5	10.0
	22161148162				9.5	12.0

Diameter (d)	Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
3	6	0.9	600	950
	8			
	10			
	12			
3.2	6	0.9	750	1000
	7			
	8			
	9			

All technical data refer to the measure mm



RIVQUICK® Coloured blind rivets


Dome head | Colored rivet brown RAL8017

Diameter (d)	Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
4	7	1.2	1200	1750
	8			
	9			
	10			
	11			
	12			
	14			
	16			
4.8	7	1.4	1850	2600
	8			
	9			
	10			
	11			
	12			
	14			
	16			

All technical data refer to the measure mm



Symbol list

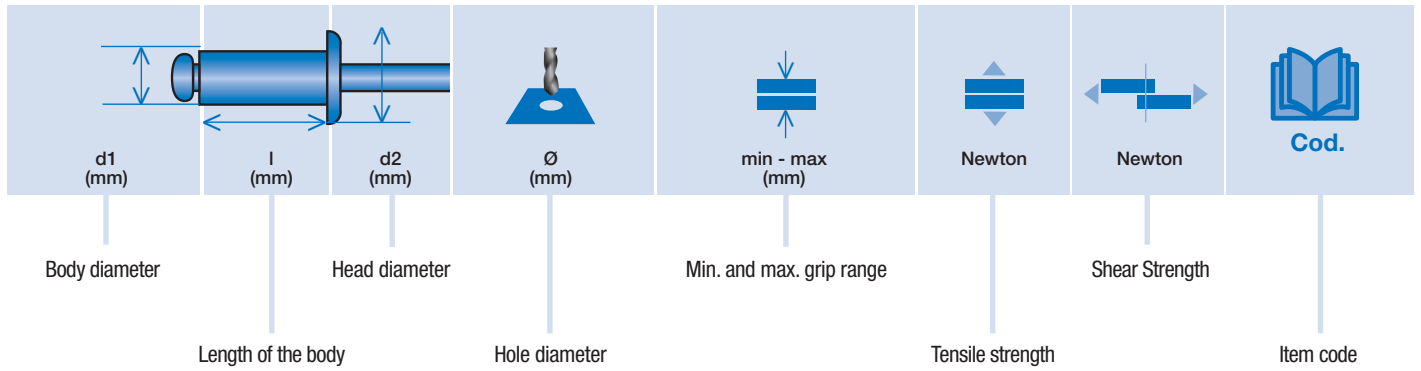

All technical data refer to the measure mm

