


SNAPLOC® Coupling

For plate fastening

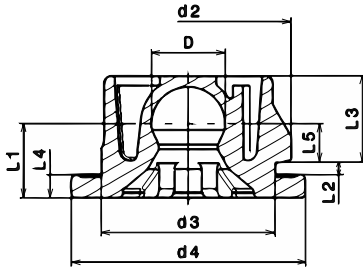

Article number	d ₂ nominal size	Depth (L ₁)	Colour	Ball diameter (D)	d ₃ nominal size	d ₄	Hardness	L ₄	L ₅	Material thickness (L ₂)
04990850001	11	7.0	black	7	10	14	93 Shore A	2.0	4.1	0.9
04990850006	11	7.0	black	7	10	14	78 Shore A	1.5	4.6	0.9
40500070026	11	6.2	black	7	10	14	38 Shore A	2.0	4.2	2
40500070027	11	8.5	black	7	10	14	86 Shore A	2.6	4.6	1.5
40500070038	11	8.2	black	7	10	14	93 Shore A	2.0	4.2	2
40500100008	25.5	16.0	black	10	22	32	78 Shore A	7.0	6	3
40500100069	21.5	10.9	black	10	18	25	69 Shore A	3.5	6	2 - 3
40500100070	21.5	10.9	black	10	16 - 18.5	25	86 Shore A	3.5	6	2 - 3
40500150009	31.5	16.0	black	15	27	34	78 Shore A	5.2	8	3 - 3.5
40500803018	22	7.9	black	8	18	25	78 Shore A	2.5	3.4	2
40590100029	21.5	10.9	black	10	18	25	78 Shore A	3.5	6	2 - 3
40590110801	22	10.9	black	8	18	25	69 Shore A	5.5	3.4	2
40600704310	11.5	8.7	black	7	10	14	69 Shore A	2.5	4.2	2
40620700310	11	8.2	black	7	10	14	78 Shore A	2.0	4.7	1.5
40700701312	17	6.7	black	7	14	20	86 Shore A	2.2	4.5 - L ₂	0.8 - 2
40700703012	17	6.7	black	7	14	20	78 Shore A	2.2	4.5 - L ₂	0.8 - 2
40700704312	17	6.7	black	7	14	20	69 Shore A	2.2	4.5 - L ₂	0.8 - 2
42500150001	37	13.5	black	15	33	38	69 Shore A	3.5	8	2 - 2.5

All technical data refer to the measure mm

